


Hauba NECV-S1W37

Broj artikla: 545974

FESTO

za ventilski blok VTSA i VTSA-F, za vlastitu ugradnju bez kabla

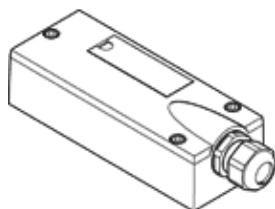

Tehnički podaci

Svojstvo	Vrednost
Područje primene	Only for multi-pin plug connection valve terminal VTSA/VTSA-F
Težina proizvoda	180 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica
Electrical connection 1, cable outlet	Angled
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	37
Electrical connection 1, occupied pins/wires	37
Electrical connection 1, type of mounting	3x M4 screws
Electrical connection 2, connection technology	Crimp contacts
Područje pogonskog napona DC	0 ... 30 V
Strujna opteretivost kod 40°C	2 A
Čvrstoća na udarno naprezanje	1 kV
Navojni spoj kabla	M20x1,5
Prečnik kabla	5 ... 13 mm
Nazivni presek provodnika	0,08 ... 0,5 mm ²
Mehanička zaštita	IP65 NEMA 4
Note on degree of protection	u montiranom stanju
Temperatura okoline	-5 ... 50 °C
PWIS conformity	VDMA24364-B1/B2-L
Klasa korozione otpornosti KBK	2 - Moderate corrosion stress
Material housing	PA