

 

Spojni vod

NEBC-A1W3-K-0.3-N-M12G5

Broj artikla: 549294

FESTO

od pogona ili sistema merne letve MLO-POT-...-TLF na senzorski interface CASM.

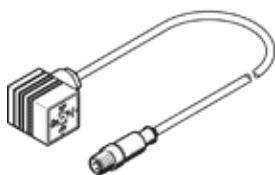

Tehnički podaci

Svojstvo	Vrednost
Zasnovano na normi	EN 61076-2-101
Cable identification	Without inscription label holder
Težina proizvoda	188 g
Električni priključak	5-polno M12x1 Utikač ravni četvorougao ni oblik / pod ugaoom
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica
Electrical connection 1, cable outlet	Angled
Electrical connection 1, connection technology	Plug pattern type A to EN 175301-803
Electrical connection 1, number of pins/wires	3
Electrical connection 1, occupied pins/wires	3
Electrical connection 1, type of mounting	Central screw M3
Electrical connection 2, function	Controller side
Electrical connection 2, design	okruglo
Electrical connection 2, connection type	Utikači
Electrical connection 2, cable outlet	Ravno
Electrical connection 2, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 2, number of pins/wires	5
Electrical connection 2, occupied pins/wires	4
Područje pogonskog napona DC	0 ... 60 V
Područje pogonskog napona AC	0 ... 60 V
Strujna opteretivost kod 40°C	4 A
Čvrstoća na udarno naprezanje	1,5 kV
Priključak uzemljenja	postoji
Shielding	Da
Dužina kabla	0,3 m
Svojstvo kabla	Standard
Uslovi ispitivanja kabla	Uslovi ispitivanja na zahtev
Min. radijus savijanja kabla	90 mm
Bending radius, fixed cable installation	≥ 90 mm
Prečnik kabla	5,9 mm
Dozvoljeni prečnik kabla	5,7 ... 6,1 mm
Struktura kabla	4x0,34
Nazivni presek provodnika	0,34 mm ²
Mehanička zaštita	IP65
Note on degree of protection	u montiranom stanju
Temperatura okoline	-25 ... 80 °C
Temperatura okoline kod pokretnog postepenja kablova	-5 ... 70 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions

Svojstvo	Vrednost
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komfornost
Stepen zagađenja	3
Klasa korozione otpornosti KBK	0 - No corrosion stress
Material cable sheath	PVC TPE-U(PUR)
Boja izolacije	sivo
Material housing	PA TPE-U(PUR)
Boja kućišta	crno
Material insulation	PVC