


Utičnica MSSD-N

Broj artikla: 550067

★ Kernprogramm

za elektromagnetne kalemове MD-2/2-... I MH-2/2-...

FESTO

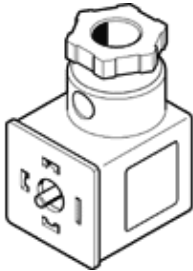

Tehnički podaci

| Svojstvo | Vrednost |
|--|---|
| Zasnovano na normi | EN 175301-803 |
| Cable outlet | Angled |
| Težina proizvoda | 30 g |
| Electrical connection 1, design | ugaono |
| Electrical connection 1, connection type | Utičnica |
| Electrical connection 1, connection technology | Plug pattern type A to EN 175301-803 |
| Electrical connection 1, number of pins/wires | 3 |
| Electrical connection 1, type of mounting | na elektromagnetnom ventilu sa središnjim vijkom M3 |
| Electrical connection 2, connection technology | Vijčana stezaljka |
| Područje pogonskog napona DC | 0 ... 24 V |
| Područje pogonskog napona AC | 0 ... 250 V |
| Strujna opteretivost kod 40°C | 16 A |
| Navojni spoj kabla | M20x1,5 |
| Prečnik kabla | 8 ... 10 mm |
| Nazivni presek provodnika | 1,5 mm ² |
| Mehanička zaštita | IP65 |
| Note on degree of protection | u montiranom stanju |
| Temperatura okoline | -25 ... 80 °C |
| PWIS conformity | VDMA24364 zone III |
| Materijal - napomena | RoHS komformnost |
| Material housing | PA ojačan |
| Boja kućišta | crno |
| Material screws | Čelik |
| Material seals | VMQ |