 



# Krajnja ploča VMPAL-EPL-SD44

Broj artikla: 560939

FESTO

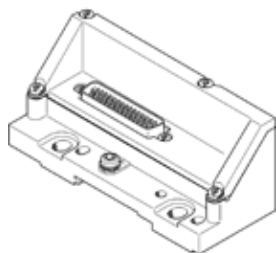

## Tehnički podaci

| Svojstvo                                       | Vrednost   |
|--|--|
| Širina   | 43 mm  |
| Dužina   | 107,3 mm   |
| Maks. broj ventilskih mesta                    | 32   |
| Struktura ventilskog bloka                     | Valve sizes can be mixed                         |
| Maksimalni broj elektromagnetnih kalema        | 32   |
| Operating pressure MPa                         | -0,09 ... 1 MPa                                  |
| Pogonski pritisak                              | -0,9 ... 10 bar                                  |
| Pilot pressure MPa                             | 0,3 ... 0,8 MPa                                  |
| Pritisak upravljanja                           | 3 ... 8 bar                                      |
| Nazivni pogonski napon DC                      | 24 V   |
| Klasa korozione otpornosti KBK                 | 3 - High corrosion stress                        |
| PWIS conformity                                | VDMA24364-B1/B2-L                                |
| Mehanička zaštita                              | IP67   |
| Note on degree of protection                   | u montiranom stanju<br>with accessories VMPAL-KM |
| Temperatura okoline                            | -5 ... 50 °C                                     |
| Težina proizvoda                               | 190 g  |
| Electrical connection 1, function              | Multipol   |
| Electrical connection 1, connection type       | Utikači  |
| Electrical connection 1, connection technology | Sub-D  |
| Electrical connection 1, number of pins/wires  | 44   |
| Materijal - napomena                           | RoHS komformnost                                 |
| Material end plate                             | Aluminijumski odlivak<br>PA ojačan               |