
 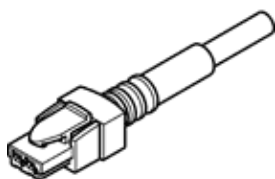


# Vod utičnice

## NEBV-HSG2-P-1-N-LE2

Broj artikla: 566667

FESTO



## Tehnički podaci

| Svojstvo                                       | Vrednost                             |
|--|--------------------------------------|
| Cable identification                           | Without inscription label holder     |
| Položaj ugradnje                               | proizvoljno                          |
| Težina proizvoda                               | 16 g                                 |
| Electrical connection 1, function              | Field device side                    |
| Electrical connection 1, design                | ugaono                               |
| Electrical connection 1, connection type       | Utičnica                             |
| Electrical connection 1, cable outlet          | Ravno                                |
| Electrical connection 1, connection technology | Connection pattern S                 |
| Electrical connection 1, number of pins/wires  | 2                                    |
| Electrical connection 1, occupied pins/wires   | 2                                    |
| Electrical connection 1, type of mounting      | Snap-in locking                      |
| Electrical connection 2, function              | Controller side                      |
| Electrical connection 2, connection type       | Kabl                                 |
| Electrical connection 2, connection technology | otvoreni kraj                        |
| Electrical connection 2, number of pins/wires  | 2                                    |
| Electrical connection 2, occupied pins/wires   | 2                                    |
| Područje pogonskog napona DC                   | 0 ... 60 V                           |
| Strujna opteretivost kod 40°C                  | 3 A                                  |
| Dužina kabla                                   | 1 m                                  |
| Svojstvo kabla                                 | Za statičke namene                   |
| Prečnik kabla                                  | 3,4 mm                               |
| Struktura kabla                                | 2x0,14                               |
| Nazivni presek provodnika                      | 0,14 mm <sup>2</sup>                 |
| Krajevi žica                                   | Sheath removed<br>Cut off bluntly    |
| Mehanička zaštita                              | IP40                                 |
| Note on degree of protection                   | u montiranom stanju                  |
| Temperatura okoline                            | -5 ... 60 °C                         |
| CE znak (vidi izjavu o usklađenosti)           | in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity)   | To UK RoHS instructions              |
| PWIS conformity                                | VDMA24364-B2-L                       |
| Materijal - napomena                           | RoHS komfornost                      |
| Material cable sheath                          | TPE-U(PUR)                           |
| Boja izolacije                                 | sivo                                 |
| Material housing                               | POM                                  |
| Boja kućišta                                   | crno                                 |
| Material electrical contact                    | Bakarna legura<br>pocinkovano        |
| Material insulation                            | PVC                                  |