 



Krajnja ploča VMPAL-EPL-SD9-IP40

Broj artikla: 570777

FESTO

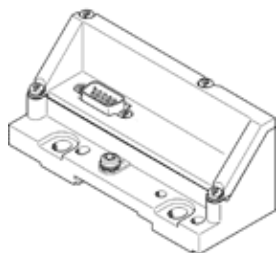

Tehnički podaci

Svojstvo	Vrednost
Širina	43 mm
Dužina	107,3 mm
Maks. broj ventilskih mesta	8
Struktura ventilskog bloka	Valve sizes can be mixed
Maksimalni broj elektromagnetnih kalema	8
Operating pressure MPa	-0,09 ... 1 MPa
Pogonski pritisak	-0,9 ... 10 bar
Pilot pressure MPa	0,3 ... 0,8 MPa
Pritisak upravljanja	3 ... 8 bar
Nazivni pogonski napon DC	24 V
Klasa korozione otpornosti KBK	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Mehanička zaštita	IP40
Note on degree of protection	u montiranom stanju
Temperatura okoline	-5 ... 50 °C
Težina proizvoda	190 g
Electrical connection 1, function	Multipol
Electrical connection 1, connection type	Utikači
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	9
Materijal - napomena	RoHS komformnost
Material end plate	Aluminijumski odlivak PA ojačan