


# Utični konektor NECU-FCG40-K

Broj artikla: 570895

FESTO

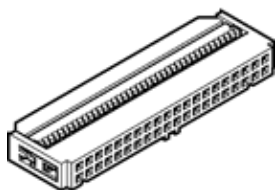

## Tehnički podaci

Svojstvo	Vrednost
Odgovara standardu	EN 60603-13
Frekvencija priključivanja	50
Cable outlet	Ravno
Težina proizvoda	5 g
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica
Electrical connection 1, connection technology	Connection pattern FC
Electrical connection 1, number of pins/wires	40
Electrical connection 1, type of mounting	Snap-in locking
Electrical connection 2, connection technology	Insulation displacement connector
Područje pogonskog napona DC	0 ... 30 V
Strujna opteretivost kod 40°C	1,5 A
Nazivni presek provodnika	0,13 mm <sup>2</sup>
Nominal conductor cross section (AWG)	AWG26
Mehanička zaštita	IP40
Temperatura okoline	-5 ... 50 °C
PWIS conformity	VDMA24364-B1/B2-L
Materijal - napomena	RoHS komfornost
Klasa korozione otpornosti KBK	0 - No corrosion stress
Material housing	PBT ojačan
Material electrical contact	Bronza pozlaćeno