


Spojni vod NEBV-

Broj artikla: 8003577

FESTO

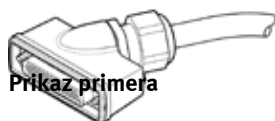

Tehnički podaci

Ukupni list podataka - Pojedinačne vrednosti zavise od Vaše konfiguracije.

Svojstvo	Vrednost
Dodatne funkcije	Smanjenje struje držanja Zaštitni krug
Cable identification	Without inscription label holder
Frekvencija priključivanja	50
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica Socket, slim
Electrical connection 1, cable outlet	Ravno Angled
Electrical connection 1, connection technology	Connection pattern ZC, self-tapping screw Connection pattern ZC, metric screw Plug pattern type C to EN 175301-803 Sub-D
Electrical connection 1, number of pins/wires	2 25 4 44
Electrical connection 2, function	Controller side
Electrical connection 2, design	ugaono okruglo
Electrical connection 2, connection type	Kabl Utikači
Electrical connection 2, cable outlet	Ravno Angled
Electrical connection 2, connection technology	Connection pattern ZB, self-tapping screw M8x1, A-coded to EN 61076-2-104 otvoreni kraj
Electrical connection 2, number of pins/wires	2 25 3 44
Područje pogonskog napona DC	0 ... 230 V
Područje pogonskog napona AC	0 ... 230 V
Dužina kabla	0,5 ... 30 m
Svojstvo kabla	Standard Suitable for energy chains
Uslovi ispitivanja kabla	Uslovi ispitivanja na zahtev
CE znak (vidi izjavu o usklađenosti)	prema EU-EMV-smernici prema EU-niski napon-smernica in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment To UK instructions for EMC To UK RoHS instructions

Svojstvo	Vrednost
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komfornost
Material cable sheath	PVC TPE-U(PUR)
Boja izolacije	sivo