
 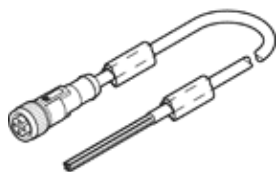


Spojni vod NEBS-M12G5-ES-5-LE5

Broj artikla: 8030962

FESTO



Tehnički podaci

Svojstvo	Vrednost
Cable identification	with 2x label holders
Težina proizvoda	276 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	okruglo
Electrical connection 1, connection type	Utičnica
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 1, number of pins/wires	5
Electrical connection 1, occupied pins/wires	5
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabl
Electrical connection 2, connection technology	otvoreni kraj
Electrical connection 2, number of pins/wires	5
Electrical connection 2, occupied pins/wires	5
Područje pogonskog napona DC	0 ... 60 V
Područje pogonskog napona AC	0 ... 48 V
Strujna opteretivost kod 40°C	4 A
Čvrstoća na udarno naprezanje	1,5 kV
Shielding	Da
Dužina kabla	5 m
Svojstvo kabla	Suitable for energy chains
Uslovi ispitivanja kabla	Uslovi ispitivanja na zahtev
Bending radius, fixed cable installation	≥ 26 mm
Bending radius, flexible cable installation	≥ 52 mm
Prečnik kabla	5,25 mm
Odstupanje prečnika kabla	± 0,2 mm
Struktura kabla	5x0,34 zaslonjeno
Nazivni presek provodnika	0,34 mm ²
Krajevi žica	Cut off bluntly
Mehanička zaštita	IP65 IP67
Note on degree of protection	u montiranom stanju
Temperatura okoline	-40 ... 80 °C
Temperatura okoline kod pokretnog postepenja kablova	-25 ... 60 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komformnost
Stepen zagađenja	3
Material cable sheath	TPE-U(PUR)
Boja izolacije	crno
Material seals	NBR
Material electrical contact	Nickel-plated and gold-plated bronze
Material insulation	PP