


# Spojni vod NEBS-M12G5-ES-10-LE5

Broj artikla: 8030963

FESTO

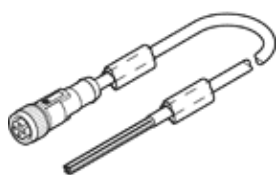

## Tehnički podaci

| Svojstvo   | Vrednost   |
|--|--|
| Cable identification                                 | with 2x label holders                            |
| Težina proizvoda                                     | 528 g  |
| Electrical connection 1, function                    | Field device side                                |
| Electrical connection 1, design                      | okruglo  |
| Electrical connection 1, connection type             | Utičnica   |
| Electrical connection 1, cable outlet                | Ravno  |
| Electrical connection 1, connection technology       | M12x1, A-coded in accordance with EN 61076-2-101 |
| Electrical connection 1, number of pins/wires        | 5  |
| Electrical connection 1, occupied pins/wires         | 5  |
| Electrical connection 1, type of mounting            | Screw lock                                       |
| Electrical connection 2, function                    | Controller side                                  |
| Electrical connection 2, connection type             | Kabl   |
| Electrical connection 2, connection technology       | otvoreni kraj                                    |
| Electrical connection 2, number of pins/wires        | 5  |
| Electrical connection 2, occupied pins/wires         | 5  |
| Područje pogonskog napona DC                         | 0 ... 60 V                                       |
| Područje pogonskog napona AC                         | 0 ... 48 V                                       |
| Strujna opteretivost kod 40°C                        | 4 A  |
| Čvrstoća na udarno naprezanje                        | 1,5 kV   |
| Shielding  | Da   |
| Dužina kabla   | 10 m   |
| Svojstvo kabla                                       | Suitable for energy chains                       |
| Uslovi ispitivanja kabla                             | Uslovi ispitivanja na zahtev                     |
| Bending radius, fixed cable installation             | ≥ 26 mm  |
| Bending radius, flexible cable installation          | ≥ 52 mm  |
| Prečnik kabla  | 5,25 mm  |
| Odstupanje prečnika kabla                            | ± 0,2 mm   |
| Struktura kabla                                      | 5x0,34<br>zaslonjeno                             |
| Nazivni presek provodnika                            | 0,34 mm <sup>2</sup>                             |
| Krajevi žica   | Cut off bluntly                                  |
| Mehanička zaštita                                    | IP65<br>IP67                                     |
| Note on degree of protection                         | u montiranom stanju                              |
| Temperatura okoline                                  | -40 ... 80 °C                                    |
| Temperatura okoline kod pokretnog postepenja kablova | -25 ... 60 °C                                    |
| CE znak (vidi izjavu o usklađenosti)                 | in accordance with EU RoHS directive             |
| UKCA marking (see declaration of conformity)         | To UK RoHS instructions                          |
| PWIS conformity                                      | VDMA24364-B2-L                                   |
| Materijal - napomena                                 | RoHS komformnost                                 |
| Stepen zagađenja                                     | 3  |
| Material cable sheath                                | TPE-U(PUR)                                       |
| Boja izolacije                                       | crno   |
| Material seals                                       | NBR  |
| Material electrical contact                          | Nickel-plated and gold-plated bronze             |
| Material insulation                                  | PP   |