

# Spojni vod


 
## NEBS-SM16G24-K-5-N-LE24

Broj artikla: 8048653

Komponenta koja će prestati da se proizvodi

Komponenta se više ne proizvodi. Isporučuje se do 2025. Vidi Support Portal za alternativni proizvod.

FESTO

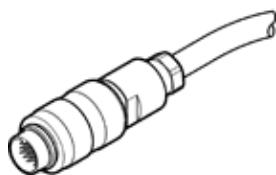

## Tehnički podaci

Svojstvo	Vrednost
Zasnovano na normi	EN 61076-2-106
Odgovara standardu	DIN 47100
Cable identification	Without inscription label holder
Težina proizvoda	745 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	okruglo
Electrical connection 1, connection type	Utikači
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	M16x0,75
Electrical connection 1, number of pins/wires	24
Electrical connection 1, occupied pins/wires	24
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabl
Electrical connection 2, connection technology	otvoreni kraj
Electrical connection 2, number of pins/wires	25
Electrical connection 2, occupied pins/wires	24
Područje pogonskog napona DC	30 V
Strujna opteretivost kod 40°C	1 A
Čvrstoća na udarno naprezanje	500 V
Dužina kabla	5 m
Svojstvo kabla	Standard
Bending radius, fixed cable installation	> 51 mm
Bending radius, flexible cable installation	> 127,5 mm
Prečnik kabla	8,5 mm
Struktura kabla	25x0,14
Nazivni presek provodnika	0,14 mm <sup>2</sup>
Krajevi žica	Cut off bluntly
Mehanička zaštita	IP67
Temperatura okoline	-30 ... 70 °C
Temperatura okoline kod pokretnog postepenja kablova	-5 ... 70 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komformnost
Stepen zagađenja	1
Material cable sheath	PVC
Boja izolacije	sivo
Material housing	PA
Material screw-type lock	Nickel-plated brass
Material electrical contact	Brass, gold-plated
Material insulation	PVC