 



# Spojni vod NEBS-L1G4-K-1-N-M12G4

Broj artikla: 8091514

FESTO

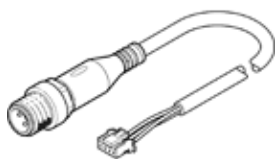

## Tehnički podaci

Svojstvo	Vrednost
Cable identification	Without inscription label holder
Frekvencija priključivanja	100
Težina proizvoda	40 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	Connection pattern L1J
Electrical connection 1, number of pins/wires	4
Electrical connection 1, occupied pins/wires	4
Electrical connection 1, type of mounting	Snap-in locking
Electrical connection 2, function	Controller side
Electrical connection 2, design	okruglo
Electrical connection 2, connection type	Utikači
Electrical connection 2, cable outlet	Ravno
Electrical connection 2, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 2, number of pins/wires	4
Electrical connection 2, occupied pins/wires	4
Electrical connection 2, type of mounting	Screw-type lock with hex A/F 13 mm and longitudinal knurl
Područje pogonskog napona DC	0 ... 30 V
Strujna opteretivost kod 40°C	1 A
Čvrstoća na udarno naprezanje	0,8 kV
Dužina kabla	1 m
Svojstvo kabla	Standard
Uslovi ispitivanja kabla	Uslovi ispitivanja na zahtev
Bending radius, fixed cable installation	≥ 14 mm
Bending radius, flexible cable installation	≥ 46 mm
Prečnik kabla	4,5 mm
Odstupanje prečnika kabla	± 0,1 mm
Struktura kabla	4x0,25
Nazivni presek provodnika	0,25 mm <sup>2</sup>
Mehanička zaštita	IP65 IP67 IP69K
Note on degree of protection	IP40 for plug connection pattern L1J u montiranom stanju
Temperatura okoline	-20 ... 60 °C
Temperatura okoline kod pokretnog postepenja kablova	-5 ... 60 °C
Temperatura ležaja	-20 ... 60 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komfornost Bez halogena
Stepen zagađenja	2
Klasa korozione otpornosti KBK	2 - Moderate corrosion stress

Svojstvo	Vrednost
Material cable sheath	TPE-U(PUR)
Boja izolacije	sivo
Material housing	PA TPE-U(PUR)
Boja kućišta	crno belo
Material screw-type lock	Nickel-plated brass
Material electrical contact	Tin-plated bronze Brass, gold-plated
Material insulation	PP