


 
Spojni vod NEBC-U7G10-EH-30-N-S-U5G9

Broj artikla: 8093272

Komponenta koja će prestati da se proizvodi

Komponenta se više ne proizvodi. Isporučuje se do 2025. Vidi Support Portal za alternativni proizvod.

FESTO

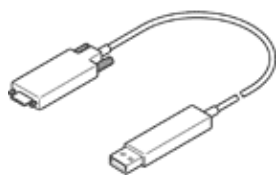

Tehnički podaci

Svojstvo	Vrednost
Dodatne funkcije	Hybrid cable
Cable identification	Without inscription label holder
Težina proizvoda	645 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utikači
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	USB 3.0 type B micro
Electrical connection 1, number of pins/wires	10
Electrical connection 1, occupied pins/wires	9
Electrical connection 1, type of mounting	2x screws M2x0.4
Electrical connection 2, function	Controller side
Electrical connection 2, design	ugaono
Electrical connection 2, connection type	Utikači
Electrical connection 2, cable outlet	Ravno
Electrical connection 2, connection technology	USB 3.0 type A
Electrical connection 2, number of pins/wires	9
Electrical connection 2, occupied pins/wires	9
Electrical connection 2, type of mounting	Plug-in
Područje pogonskog napona DC	4,75 ... 5,25 V
Nazivni pogonski napon DC	5 V
Strujna opteretivost kod 40°C	0,9 A
Dužina kabela	30 m
Svojstvo kabela	prikladno za energetski lanac
Bending radius, fixed cable installation	≥ 20 mm
Bending radius, flexible cable installation	≥ 10 mm
Prečnik kabela	3,1 mm
Odstupanje prečnika kabela	± 0,2 mm
Mehanička zaštita	IP20
Note on degree of protection	u montiranom stanju
Temperatura okoline	-5 ... 50 °C
Temperatura okoline kod pokretnog postepenja kablova	-5 ... 50 °C
Temperatura ležaja	-40 ... 90 °C
CE znak (vidi izjavu o usklađenosti)	prema EU-EMV-smernici
PWIS conformity	VDMA24364 zone III
Materijal - napomena	RoHS komformnost
Stepen zagađenja	1
Klasa korozione otpornosti KBK	0 - No corrosion stress
Material cable sheath	PVC
Boja izolacije	crno
Material housing	Anodised wrought aluminium alloy
Boja kućišta	srebrno