
 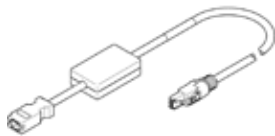


# Adapter NEFM-REG6-K-0.5-B-R3G8

Broj artikla: 8097195

FESTO



## Tehnički podaci

Svojstvo	Vrednost
Dodatne funkcije	For battery
Težina proizvoda	64 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	Connection pattern RE
Electrical connection 1, number of pins/wires	6
Electrical connection 1, occupied pins/wires	4
Electrical connection 2, function	Controller side
Electrical connection 2, design	ugaono
Electrical connection 2, connection type	Utikači
Electrical connection 2, cable outlet	Ravno
Electrical connection 2, connection technology	RJ45
Electrical connection 2, number of pins/wires	8
Electrical connection 2, occupied pins/wires	6
Područje pogonskog napona DC	0 ... 30 V
Područje pogonskog napona AC	0 ... 30 V
Strujna opteretivost kod 40°C	1,6 A
Čvrstoća na udarno naprezanje	2 kV
Shielding	Da
Dužina kabla	0,5 m
Svojstvo kabla	Standard
Uslovi ispitivanja kabla	Uslovi ispitivanja na zahtev
Bending radius, fixed cable installation	≥ 68 mm
Prečnik kabla	6,8 mm
Struktura kabla	4x(2x0,081)+(2x0,205)
Nazivni presek provodnika	0,081 mm <sup>2</sup> 0,205 mm <sup>2</sup>
Nominal conductor cross section (AWG)	AWG24 AWG28
Mehanička zaštita	IP20
Note on degree of protection	u montiranom stanju
Temperatura okoline	-40 ... 80 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
Materijal - napomena	RoHS komfornost
Stepen zagađenja	3
Klasa korozione otpornosti KBK	0 - No corrosion stress
Material cable sheath	PVC
Boja izolacije	crno
Material housing	PVC
Boja kućišta	sivo
Material insulation	PVC