
 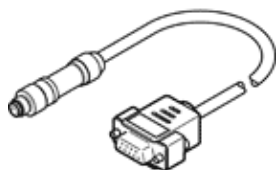


# Spojni vod

## NEBC-M8G4-ES-1.5-N-SB-S1G9-RS2-S7

Broj artikla: 8099218

FESTO



## Tehnički podaci

Svojstvo	Vrednost
Protokol	RS232
Cable identification	sa priborom
Položaj ugradnje	proizvoljno
Electrical connection 1, function	Field device side
Electrical connection 1, design	okruglo
Electrical connection 1, connection type	Utikači
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	M8x1, A-coded to EN 61076-2-104
Electrical connection 1, number of pins/wires	4
Electrical connection 1, occupied pins/wires	3
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, function	Controller side
Electrical connection 2, design	ugaono
Electrical connection 2, connection type	Utičnica
Electrical connection 2, cable outlet	Ravno
Electrical connection 2, connection technology	Sub-D
Electrical connection 2, number of pins/wires	9
Electrical connection 2, occupied pins/wires	8
Electrical connection 2, type of mounting	2 screws 4-40 UNC
Područje pogonskog napona DC	0 ... 24 V
Nazivni pogonski napon DC	24 V
Strujna opteretivost kod 40°C	4 A
Čvrstoća na udarno naprezanje	1,5 kV
Shielding	Da
Dužina kabla	1,5 m
Svojstvo kabla	Suitable for energy chains
Uslovi ispitivanja kabla	Uslovi ispitivanja na zahtev
Bending radius, fixed cable installation	≥ 24 mm
Bending radius, flexible cable installation	≥ 47 mm
Prečnik kabela	4,6 mm
Odstupanje prečnika kabla	± 0,1 mm
Struktura kabla	3x0,34
Nazivni presek provodnika	0,34 mm <sup>2</sup>
Mehanička zaštita	IP67
Note on degree of protection	IP20 for Sub-D socket u montiranom stanju
Temperatura okoline	0 ... 50 °C
Temperatura okoline kod pokretnog postepenja kablova	0 ... 50 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
Materijal - napomena	RoHS komformnost
Stepen zagađenja	2
Material cable sheath	TPE-U(PUR)
Boja izolacije	crno