


Spojni vod

NEBV-Q7G2-PD-0.1-N-LE2

Broj artikla: 8115892

FESTO

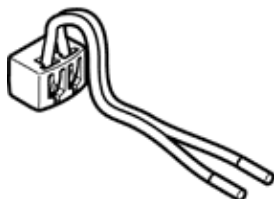

Tehnički podaci

Svojstvo	Vrednost
Cable identification	Without inscription label holder
Frekvencija priključivanja	20
Težina proizvoda	0,5 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	Connection pattern Q7
Electrical connection 1, number of pins/wires	2
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, type of mounting	Plug-in
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Twin wire
Electrical connection 2, connection technology	otvoreni kraj
Electrical connection 2, number of pins/wires	2
Electrical connection 2, occupied pins/wires	2
Područje pogonskog napona DC	0 ... 30 V
Strujna opteretivost kod 40°C	0,3 A
Čvrstoća na udarno naprezanje	1,2 kV
Zaštita od zamene polova	ne
Priključak uzemljenja	ne postoji
Shielding	ne
Napomena za pogon	Operate only with external power reduction
Dužina kabla	0,1 m
Svojstvo kabla	Basic
Uslovi ispitivanja kabla	Uslovi ispitivanja na zahtev
Bending radius, fixed cable installation	≥ 11 mm
Bending radius, flexible cable installation	≥ 16,5 mm
Prečnik kabela	1,1 mm
Struktura kabla	2x0,08
Nazivni presek provodnika	0,08 mm ²
Nominal conductor cross section (AWG)	AWG28
Krajevi žica	pocinkovano
Mehanička zaštita	IP40
Temperatura okoline	0 ... 50 °C
Temperatura ležaja	-20 ... 70 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komfornost
Klasa korozione otpornosti KBK	0 - No corrosion stress
Material housing	PA ojačan
Boja kućišta	crno
Material electrical contact	Gold-plated copper alloy
Material insulation	PVC