


Spojni vod

NEBC-R3Z12G20-KH-10-N-SBS-RSG17-ET-S1

Broj artikla: 8126917

FESTO

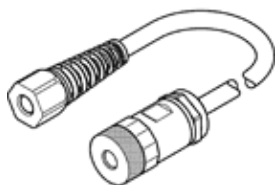

Tehnički podaci

Svojstvo	Vrednost
Cable identification	Without inscription label holder
Težina proizvoda	1.300 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Plug and socket strip
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	RJ45 and socket strip 12 pins, 2 rows
Electrical connection 1, number of pins/wires	20
Electrical connection 1, occupied pins/wires	14
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, function	Controller side
Electrical connection 2, design	okruglo
Electrical connection 2, connection type	Hybrid plugs
Electrical connection 2, cable outlet	Ravno
Electrical connection 2, number of pins/wires	17
Electrical connection 2, occupied pins/wires	14
Electrical connection 2, type of mounting	Threaded
Područje pogonskog napona DC	0 ... 24 V
Nazivni pogonski napon DC	24 V
Strujna opteretivost kod 40°C	11,7 A
Čvrstoća na udarno naprezanje	6 kV
Shielding	ne
Dužina kabela	10 m
Svojstvo kabela	Standard
Uslovi ispitivanja kabela	Uslovi ispitivanja na zahtev
Bending radius, fixed cable installation	≥ 130 mm
Bending radius, flexible cable installation	≥ 130 mm
Prečnik kabela	8 mm
Odstupanje prečnika kabela	± 1 mm
Struktura kabela	4x(1x0,128)+10x0,128
Nazivni presek provodnika	0,128 mm ²
Mehanička zaštita	IP65
Note on degree of protection	u montiranom stanju
Temperatura okoline	0 ... 40 °C
Temperatura okoline kod pokretnog postepenja kablova	0 ... 40 °C
Temperatura ležaja	-20 ... 70 °C
CE znak (vidi izjavu o usklađenosti)	prema EU-niski napon-smernica
PWIS conformity	VDMA24364 zone III
Materijal - napomena	RoHS komformnost
Stepen zagađenja	3
Klasa korozione otpornosti KBK	0 - No corrosion stress
Material cable sheath	TPE-U(PUR)
Boja izolacije	crveno
Material insulation	PP