 



# 消音器 U-1/2-B-NPT

料號: 12741

FESTO

For reducing noise and avoiding contamination at the exhaust ports of pneumatic components.

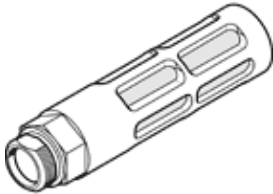

## 技術參數

特性	值
裝配位置	任何
Operating pressure for entire temperature range	0 ... 1 MPa
操作壓力的完整溫度範圍	0 ... 10 bar
Operating pressure for entire temperature range	0 ... 145 psi
相對於大氣的流量	6,500 l/min
操作介質	壓縮空氣符合 ISO8573-1:2010 [7:-:-]
注意: 操作和嚮導介質	潤滑操作可行
耐腐蝕等級 CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
聲壓等級	80 dB(A)
環境溫度	-10 ... 70 °C
產品重量	75 g
氣壓連接	1/2 NPT
Material of silencer insert	PE
Material of threaded plug	鋁
材料備註	符合 RoHS
Material housing	鋁