


T形快插接頭 CRQST-4

料號: 130668

FESTO

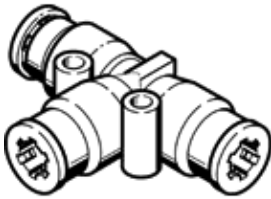

技術參數

| 特性 | 值 |
|---|--|
| 尺寸 | 標準 |
| 額定尺寸 | 2.1 mm |
| 裝配位置 | 任何 |
| 設計 | T-形 |
| 容器尺寸 | 1 |
| 設計結構 | 推/拉原理 |
| Operating pressure for entire temperature range | -0.095 ... 1 MPa |
| 操作壓力的完整溫度範圍 | -0.95 ... 10 bar |
| Operating pressure for entire temperature range | -13.775 ... 145 psi |
| 操作壓力注意事項 | Water: max. 0.6 MPa at max. 50°C |
| 操作介質 | 壓縮空氣符合 ISO8573-1:2010 [7:-:-] Water (liquid, free of ice) |
| 注意: 操作和嚮導介質 | 潤滑操作可行 |
| 耐腐蝕等級 CRC | 4 - Very high corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Food-safe | See Supplementary material information |
| 環境溫度 | -15 ... 120 °C |
| 產品重量 | 18 g |
| 輸出數量 | 2 |
| 輸送管線的數量 | 1 |
| 可使用電線 | PFAN |
| 氣壓連接, 氣口 1 | For tubing outside diameter 4 mm |
| 氣壓連接, 氣口 2 | For tubing outside diameter 4 mm |
| 材料備註 | 符合 RoHS |
| Material housing | 高合金鋼, 耐腐蝕 |
| Material release ring | 高合金鋼, 耐腐蝕 |
| Material of tubing seal | FPM |
| Material of tube retaining claw | 高合金鋼, 耐腐蝕 |
| Thrust ring material | 高合金鋼, 耐腐蝕 |