 



# 編程電纜

## NEBC-U1G4-K-1.8-N-U2G4

料號: 1501332

FESTO

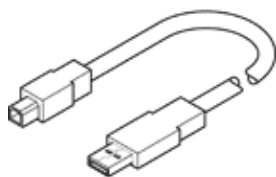

### 技術參數

特性	值
Cable identification	Without inscription label holder
裝配位置	任何
電氣連接 1	Straight plug, USB 2.0 type A, 4-pin
Electrical connection 1, function	Field device side
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	USB 2.0 type B
Electrical connection 1, number of pins/wires	4
Electrical connection 1, occupied pins/wires	4
電氣連接 2	Straight plug, USB 2.0 type B, 4-pin
Electrical connection 2, function	Controller side
Electrical connection 2, design	有角的
Electrical connection 2, connection type	插頭
Electrical connection 2, cable outlet	直的
Electrical connection 2, connection technology	USB 2.0 Typ A
Electrical connection 2, number of pins/wires	4
Electrical connection 2, occupied pins/wires	4
電纜長度	1.8 m
電纜屬性	標準
CE 符號 (參見符合的標準)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
材料備註	符合 RoHS
耐腐蝕等級 CRC	0 - No corrosion stress