


L型快插單向接頭

QSKL-1/2-12

料號: 153438

FESTO

360° orientable, male thread with external hexagon.

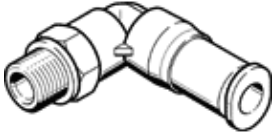

技術參數

| 特性 | 值 |
|---|---|
| 尺寸 | 標準 |
| 額定尺寸 | 6.2 mm |
| Approved tubing type | PAN- PAN-MF- PAN-R- PAN-V0- PEN- PFAN- PLN- PTFEN- PUN- PUN-CM- PUN-DUO- PUN-H- PUN-H-DUO- PUN-S- PUN-S-DUO- PUN-V0- |
| Tubing insertion depth | 22.9 mm |
| 柱頭螺栓上的密封件類型 | 外表層 |
| 裝配位置 | 任何 |
| 設計 | L-shape |
| 容器尺寸 | 1 |
| 設計結構 | 推/拉原理 |
| Operating pressure for entire temperature range | -0.095 ... 0.6 MPa |
| 操作壓力的完整溫度範圍 | -0.95 ... 6 bar |
| Operating pressure for entire temperature range | -13.775 ... 87 psi |
| Temperature-dependent operating pressure | -0.095 ... 1.4 MPa |
| 溫度取決於操作壓力 | -0.95 ... 14 bar |
| Temperature-dependent operating pressure | -13.775 ... 203 psi |
| Maritime classification | see certificate |
| 操作介質 | 壓縮空氣符合 ISO8573-1:2010 [7:-:-] |
| 注意: 操作和嚮導介質 | 潤滑操作可行 |
| 耐腐蝕等級 CRC | 1 - Low corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| 環境溫度 | -10 ... 80 °C |
| 額定鎖緊扭矩 | 26 Nm |
| 額定擰緊扭矩公差 | ± 20 % |
| 產品重量 | 81 g |
| 安裝類型 | External hex A/F 21 |
| 氣壓連接, 氣口 1 | 外螺紋 R1/2 |
| 氣壓連接, 氣口 2 | For tubing outside diameter 12 mm |
| 釋放環的顏色 | 藍色 |
| 材料備註 | 符合 RoHS |
| Material housing | PBT |
| Material release ring | POM |
| Material of tubing seal | NBR |
| Material of tube retaining claw | 高合金鋼, 耐腐蝕 |