

圓形氣壓缸 DSAS-25- -PPV-A

 

料號: 171966
將停止供貨的產品

端蓋具擺動軸承

Type to be discontinued. Available until 2024. See Support Portal for alternative products.

FESTO

代表範例

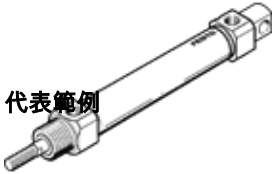

技術參數

| 特性 | 值 |
|--|-------------------------------|
| 行程 | 1 ... 500 mm |
| 活塞直徑 | 25 mm |
| 緩衝 | PPV: 兩端具可調的氣緩衝 |
| 操作壓力 | 1 ... 10 bar |
| 操作模式 | 雙動 |
| 操作介質 | 壓縮空氣符合 ISO8573-1:2010 [7:4:4] |
| 注意: 操作和嚮導介質 | 潤滑操作可行 (隨後需要進一步操作) |
| 耐腐蝕等級 CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B2-L |
| 環境溫度 | -20 ... 80 °C |
| 緩衝長度 | 17 mm |
| Theoretical force at 0.6 MPa (6 bar, 87 psi), retracting | 247.4 N |
| Theoretical force at 0.6 MPa (6 bar, 87 psi), advance | 294.5 N |
| 0 mm行程時的運動質量 | 141 g |
| 每 10 mm 行程的附加質量係數 | 6.2 g |
| 0 mm行程時的基本重量 | 212 g |
| 每 10 mm 行程所增加的重量 | 11.1 g |
| 氣壓連接 | M26x1,5 |
| Material cover | 鍛造鋁合金 |
| Material seals | NBR TPE-U(PU) |
| Material housing | 高合金鋼, 耐腐蝕 |
| Material piston rod | 高合金鋼, 耐腐蝕 |