


連接電纜

NEBM-L5G18-E-10-N-LE18

料號: 4977494
將停止供貨的產品

FESTO

Type to be discontinued. Available until 2026. See Support Portal for alternative products.

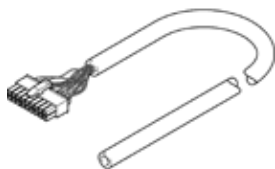

技術參數

特性	值
Cable identification	Without inscription label holder
Electrical connection 1, function	Field device side
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭插座
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	Pin allocation L5
Electrical connection 1, number of pins/wires	18
Electrical connection 1, occupied pins/wires	18
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	電纜
Electrical connection 2, connection technology	開放式終端
Electrical connection 2, number of pins/wires	18
Electrical connection 2, occupied pins/wires	18
工作電壓範圍 DC	0 ... 30 V
工作電壓範圍 AC	0 ... 30 V
在40°C時的可接受電流負載	5 A
浪湧強度	1.5 kV
電纜長度	10 m
電纜屬性	適合於拖鏈
電纜的測試條件	視需求的測試條件
Bending radius, fixed cable installation	≥ 26 mm
Bending radius, flexible cable installation	≥ 43 mm
電纜直徑	8.5 mm
電纜結構	18x0,25
導體的額定截面	0.25 mm ²
導線末端	Cut off bluntly
防護等級	IP20
Note on degree of protection	IP65 for mounting in terminal boxes
環境溫度	-40 ... 80 °C
Ambient temperature with flexible cable installation	-40 ... 80 °C
CE 符號 (參見符合的標準)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
材料備註	符合 RoHS
污染程度	3
耐腐蝕等級 CRC	0 - No corrosion stress
Material cable sheath	TPE-U(PUR)
電纜外套顏色	灰色
Material housing	PA
外殼顏色	黑色
Material insulation	TPE-E