

# 氣壓多個連接器板

## CPV14-VI-P6-1/8-D


料號: 539504

Classic - nicht für Neukonstruktionen verwenden

用於閩島 CPV.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

FESTO

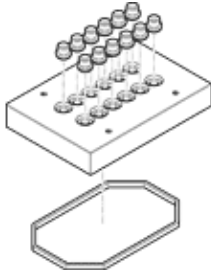

### 技術參數

特性	值
CE 符號 (參見符合的標準)	根據 EU-Ex 防爆指導原則 (ATEX)
UKCA marking (see declaration of conformity)	To UK EX instructions To UK RoHS instructions
EU以外的防爆保護認證	EPL Db (GB) EPL Db (IEC-EX) EPL Dc (IEC-EX) EPL Gb (GB) EPL Gb (IEC-EX) EPL Gc (IEC-EX)
認證核發部門	IECEX TUR 12.0002X TÜV 06 ATEX 7334 X TÜV 21 UKEX 7013 X
ATEX(防爆) 標準-氣體	II 2G
ATEX(防爆) 標準-灰塵	II 2D
防氣爆	Ex eb IIC Gb
防塵爆	Ex tb IIIC Db
周遭防爆溫度	-10°C ≤ Ta ≤ +60°C
耐腐蝕等級 CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
產品重量	400 g
材料備註	符合 RoHS 不含鹵素 Free of copper
Material seals	NBR
Material plate	鍛造鋁合金