



信號轉換器

SVE4-IS-R-HM8-2N-M8

料號: 544221

FESTO

 將感測器的類比輸出訊號轉換成切換點

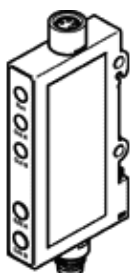

技術參數

特性	值
授權	RCM Mark c UL us - Listed (OL)
UL 環境溫度	-20 ... 60 °C
CE 符號 (參見符合的標準)	根據 EU-EMV 指導原則 in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK RoHS instructions
材料備註	符合 RoHS
信號範圍	0 - 20 mA +/-0,6 mA
環境溫度	-20 ... 70 °C
開關輸出	2xNPN
切換功能	自由編程
切換元件功能	可切換
短路強度	脈衝調制
過載承受能力	已可供應
工作電壓範圍 DC	10 ... 30 V
Electrical connection 1, connection type	插頭插座
Electrical connection 1, connection technology	M8x1, A-coded to EN 61076-2-104
Electrical connection 1, number of pins/wires	4
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, connection type	插頭
Electrical connection 2, connection technology	M8x1, A-coded to EN 61076-2-104
Electrical connection 2, number of pins/wires	4
Electrical connection 2, type of mounting	Screw lock
產品重量	19 g
Material housing	ABS
設定選項	Teach-In
防護等級	IP65
耐腐蝕等級 CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L