


端板

VMPAL-EPL-SD44

料號: 560939

FESTO

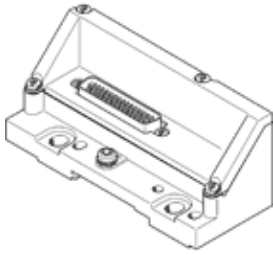

技術參數

| 特性 | 值 |
|--|-----------------------------------|
| 寬度 | 43 mm |
| 長度 | 107.3 mm |
| 閥位的最大數量 | 32 |
| 閥島結構 | Valve sizes can be mixed |
| 電磁線圈的最大數量 | 32 |
| Operating pressure MPa | -0.09 ... 1 MPa |
| 操作壓力 | -0.9 ... 10 bar |
| Pilot pressure MPa | 0.3 ... 0.8 MPa |
| 嚮導壓力 | 3 ... 8 bar |
| 額定工作電壓 DC | 24 V |
| 耐腐蝕等級 CRC | 3 - High corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| 防護等級 | IP67 |
| Note on degree of protection | 裝配狀態 with accessories VMPAL-KM |
| 環境溫度 | -5 ... 50 °C |
| 產品重量 | 190 g |
| Electrical connection 1, function | Multi-pin插頭 |
| Electrical connection 1, connection type | 插頭 |
| Electrical connection 1, connection technology | Sub-D |
| Electrical connection 1, number of pins/wires | 44 |
| 材料備註 | 符合 RoHS |
| Material end plate | 壓鑄鋁 PA-加強 |