


# 端蓋 CV-PK-4-B

料號: 6214

FESTO

用於塑料氣管接頭和倒鉤式接頭。

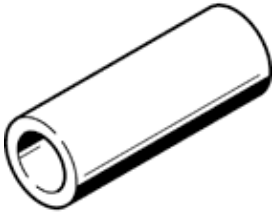

## 技術參數

特性	值
容器尺寸	10
Temperature-dependent operating pressure	-0.095 ... 1 MPa
溫度取決於操作壓力	-0.95 ... 10 bar
Temperature-dependent operating pressure	-13.775 ... 145 psi
操作介質	壓縮空氣符合 ISO8573-1:2010 [7::-]
PWIS conformity	VDMA24364-B2-L
環境溫度	-10 ... 80 °C
氣壓連接, 氣口 1	For tubing outside diameter 6 mm 用於倒鉤接頭內徑 4 mm 具螺母
材料備註	符合 RoHS
Material cap	TPE-U(PU)