

## 連接電纜


### NEBC-U7W10-KS-0.5-N-SB-U7G10

料號: 8093270  
將停止供貨的產品

FESTO

Type to be discontinued. Available until 2025. See Support Portal for alternative products.

10 9 8 7 6 5 4 3 2 1

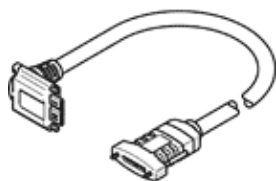

## 技術參數

特性	值
Cable identification	Without inscription label holder
產品重量	35 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭
Electrical connection 1, cable outlet	Angled
Electrical connection 1, connection technology	USB 3.0 type B micro
Electrical connection 1, number of pins/wires	10
Electrical connection 1, occupied pins/wires	9
Electrical connection 1, type of mounting	2x screws M2x0.4
Electrical connection 2, function	Controller side
Electrical connection 2, design	有角的
Electrical connection 2, connection type	插頭插座
Electrical connection 2, cable outlet	直的
Electrical connection 2, connection technology	USB 3.0 type B micro
Electrical connection 2, number of pins/wires	10
Electrical connection 2, occupied pins/wires	9
Electrical connection 2, type of mounting	2x threaded bush M2x0.4
工作電壓範圍 DC	0 ... 30 V
工作電壓範圍 AC	0 ... 30 V
在40°C時的可接受電流負載	1.4 A
浪湧強度	1 kV
Shielding	是
傳輸特性	as per system communication AP
電纜長度	0.45 m
電纜屬性	標準
電纜的測試條件	視需求的測試條件
Bending radius, fixed cable installation	>= 62 mm
Bending radius, flexible cable installation	>= 62 mm
電纜直徑	6.2 mm
電纜結構	2 x AWG22 + 2 x (2 x AWG26)C + 1 x (2 x AWG28)
導體的額定截面	0.32 mm <sup>2</sup>
防護等級	IP20
Note on degree of protection	裝配狀態
環境溫度	-10 ... 80 °C
Ambient temperature with flexible cable installation	-10 ... 80 °C
儲藏溫度	-10 ... 80 °C
PWIS conformity	VDMA24364 zone III
材料備註	符合 RoHS
污染程度	1
耐腐蝕等級 CRC	0 - No corrosion stress
Material cable sheath	PVC
電纜外套顏色	黑色
Material housing	PVC
外殼顏色	黑色
Material insulation	PVC