


# 垂直壓力氣源板 VMPA14-VSP-QS10

料號: 8110625

FESTO

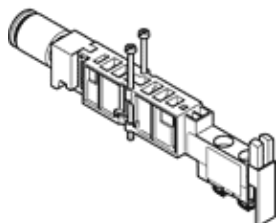

## 技術參數

特性	值
網柵尺寸	14 mm
Operating pressure MPa	-0.09 ... 1 MPa
操作壓力	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
嚮導壓力	3 ... 8 bar
操作介質	壓縮空氣符合 ISO8573-1:2010 [7:4:4]
耐腐蝕等級 CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
環境溫度	-5 ... 50 °C
產品重量	55 g
氣壓連接, 氣口 1	QS-10
材料備註	符合 RoHS
Material supply plate	PA-加強