

連接電纜


NEBC-H25G8-ES-5-N-B-LE4

料號: 8132476

將停止供貨的產品

FESTO

Type to be discontinued. Available until 2025. See Support Portal for alternative products.

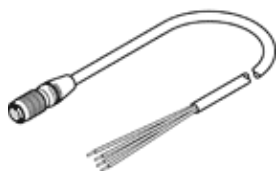

技術參數

特性	值
Cable identification	Without inscription label holder
產品重量	160 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	圓形
Electrical connection 1, connection type	插頭插座
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	HR25
Electrical connection 1, number of pins/wires	8
Electrical connection 1, occupied pins/wires	4
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	電纜
Electrical connection 2, connection technology	開放式終端
Electrical connection 2, number of pins/wires	4
Electrical connection 2, occupied pins/wires	4
工作電壓範圍 DC	0 ... 42 V
工作電壓範圍 AC	0 ... 30 V
在40°C時的可接受電流負載	1 A
浪湧強度	3 kV
Shielding	是
電纜長度	4.93 m
電纜屬性	適合於拖鏈
電纜的測試條件	視需求的測試條件
Bending radius, fixed cable installation	≥ 18.4 mm
Bending radius, flexible cable installation	≥ 34.5 mm
電纜直徑	4.6 mm
電纜結構	4x0,14
導體的額定截面	0.14 mm ²
導線末端	Cut off bluntly
防護等級	取決於連接塊
Note on degree of protection	取決於連接塊
環境溫度	-10 ... 60 °C
Ambient temperature with flexible cable installation	-5 ... 60 °C
儲藏溫度	-10 ... 60 °C
CE 符號 (參見符合的標準)	根據 EU-EMV 指導原則 in accordance with EU RoHS directive
PWIS conformity	VDMA24364 zone III
材料備註	符合 RoHS
污染程度	1
耐腐蝕等級 CRC	0 - No corrosion stress
Material cable sheath	PVC
電纜外套顏色	灰色
Material housing	鍍鎳黃銅
外殼顏色	銀
Material insulation	PPS