


# 塑料氣管 PUN-H-F-8X1,25-TBL

料號: 8153396

FESTO

This product is suitable for use with the fittings series types: QS, NPQP, NPQM, CRQS and CK.

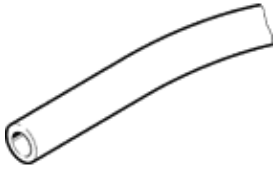

## 技術參數

特性	值
外徑	8 mm
與流量相關的彎曲半徑	37 mm
內徑	5.7 mm
最小彎曲半徑	21 mm
Instructions for use	Tubing without printing TPE-U Ether basiert
Tubing characteristics	Suitable for energy chains
Operating pressure for entire temperature range	-0.095 ... 0.6 MPa
操作壓力的完整溫度範圍	-0.95 ... 6 bar
Operating pressure for entire temperature range	-13.775 ... 87 psi
Temperature-dependent operating pressure	-0.095 ... 1 MPa
溫度取決於操作壓力	-0.95 ... 10 bar
Temperature-dependent operating pressure	-13.775 ... 145 psi
操作壓力注意事項	Water: temperature-dependent operating pressure, see diagram, max. 0.3 MPa at 0 - 60°C
操作介質	壓縮空氣符合 ISO8573-1:2010 [7:-:-] Water (liquid, free of ice)
Material fire test	UL94 HB
PWIS conformity	VDMA24364-B2-L
無塵室等級	This product is a static object, active particle generation is not possible when used correctly. Clean product before using it in a cleanroom environment and ensure it is installed correctly.
Food-safe	See declaration of conformity
環境溫度	-35 ... 60 °C
產品重量視長度而定	0.0285 kg/m
氣壓連接	For push-in connector outside diameter 8 mm 用於倒鉤接頭內徑 6 mm 具螺母
顏色	Translucent blue
肖氏硬度	D 52 +/-3
材料備註	符合 RoHS
Material tubing	TPE-U(PU)