

# FESTO

Quick Search Plus  
Version 2024-01



Copyright © Festo AG & Co. KG

# QuickSearchPlus

## 2024-01

## Release Notes

## Replace selected item in parts list

The screenshot shows the software interface with a toolbar at the top. A mouse cursor is clicking on the 'Replace' button, which is highlighted with a black box containing the number '3'. A dropdown menu is open, showing a list of parts with their designations and part numbers. The part 'AEVUZ-80-10-P-A' is selected in the dropdown, highlighted with a blue box and a black box containing the number '2'. Below the toolbar, a table shows the current parts list. The part 'AEVUZ-80-20-P-A' is selected in the table, highlighted with a blue box and a black box containing the number '1'.

Quantity	Part no.	Type	Designation	ID1
1	549194	AKM-12	Cover cap	AKM-12
1	10399	AH-06-B	Toggle lever	AH-06-B
1	157246	AEVUZ-80-20-P-A	Compact air cylinder	AEVUZ-80-20-P-A
1	157306	FUA-80	Flange mounting	FUA-80

- 1 Select a line in the parts list
- 2 Choose the **new item** in the product list
- 3 Click the **Replace** button
- 4 The line is replaced by the **new item**

The screenshot shows the software interface after the replacement. The table below shows that the part 'AEVUZ-80-20-P-A' has been replaced by 'AEVUZ-80-10-P-A'. The new part is highlighted with a blue box and a black box containing the number '4'.

Quantity	Part no.	Type	Designation	ID1
1	549194	AKM-12	Cover cap	AKM-12
1	10399	AH-06-B	Toggle lever	AH-06-B
1	157244	AEVUZ-80-10-P-A	Compact air cylinder	AEVUZ-80-10-P-A
1	157306	FUA-80	Flange mounting	FUA-80

## Insert item after selected item in parts list

1

3

2

1

Quantity	Part no.	Type	Designation	ID1
1	549194	AKM-12	Cover cap	AKM-12
1	10399	AH-06-B	Toggle lever	AH-06-B
1	157244	AEVUZ-80-10-P-A	Compact air cylinder	AEVUZ-80-10-P-A
1	157206	FUA-80	Flange mounting	FUA-80

- 1 Select a line in the parts list
- 2 Choose the **new item** in the product list
- 3 Click the **Insert** button
- 4 The **new item** is added **after** the selected line

4

Quantity	Part no.	Type	Designation	ID1
1	549194	AKM-12	Cover cap	AKM-12
1	10399	AH-06-B	Toggle lever	AH-06-B
1	157244	AEVUZ-80-10-P-A	Compact air cylinder	AEVUZ-80-10-P-A
1	157248	AEVUZ-100-10-P-A	Compact air cylinder	AEVUZ-100-10-P-A
1	157306	FUA-80	Flange mounting	FUA-80

## Insert items after selected item in parts list

3

Insert

Type	Part no.	Designation
> A	157248	AEVUZ-100-10-P-A Compact air cylinder
> A	157249	AEVUZ-100-15-P-A Compact air cylinder
> A	157250	AEVUZ-100-20-P-A Compact air cylinder
> A	157295	AEVUZ-100-15-P-A Compact air cylinder
> A	157244	AEVUZ-80-10-P-A Compact air cylinder
> A	157249	AEVUZ-100-15-P-A Compact air cylinder
> A	157296	AEVUZ-100-15-P-A Compact air cylinder
> A	157250	AEVUZ-100-20-P-A Compact air cylinder
> A	157297	AEVUZ-100-25-A-P-A Compact air cylinder

2

1

Quantity	Part no.	Type	Designation	ID1
1	549194	AKM-12	Cover cap	AKM-12
1	10399	AH-06-B	Toggle lever	AH-06-B
1	157244	AEVUZ-80-10-P-A	Compact air cylinder	AEVUZ-80-10-P-A
1	157306	FUA-80	Flange mounting	FUA-80

- 1 Select a line in the parts list
- 2 Choose **new item** (hold down Shift or CTRL)
- 3 Click the **Insert** button
- 4 The **new items** added **after** the selected line

4

Quantity	Part no.	Type	Designation	ID1
1	549194	AKM-12	Cover cap	AKM-12
1	10399	AH-06-B	Toggle lever	AH-06-B
1	157244	AEVUZ-80-10-P-A	Compact air cylinder	AEVUZ-80-10-P-A
1	157248	AEVUZ-100-10-P-A	Compact air cylinder	AEVUZ-100-10-P-A
1	157249	AEVUZ-100-15-P-A	Compact air cylinder	AEVUZ-100-15-P-A
1	157250	AEVUZ-100-20-P-A	Compact air cylinder	AEVUZ-100-20-P-A
1	157306	FUA-80	Flange mounting	FUA-80

# Online product data and QuickSearch product data are identical now

**Online**

Home > Products > Industrial automation > Tubes, fittings, plugs and cables > Pneumatic connection technology > Pneumatic fittings > Barbed fittings > CK > ACK-1/8-PK-6

**Quick connector** (designation)

ACK-1/8-PK-6 (Product tree)

7842

GTIN: 4052568020231

<b>Pneumatic connection, port 1</b>	Female thread G1/8
<b>Pneumatic connection, port 2</b>	For tubing outside diameter of 8 mm - For barbed fitting inside diameter of 6 mm with nut
<b>Ambient temperature</b>	-10 °C - 60 °C

**Top features**

- Industrial automation
  - Actuators
  - Motors and servo drives
  - Industrial robots
  - Vacuum technologies
  - Valves and valve technology
  - Sensors
  - Machine vision
  - Compressed air preparation
- Tubes, fittings, plugs and cables
  - Electrical connection technology
  - Pneumatic connection technology
    - Pneumatic tubing
    - Pneumatic fittings
      - Push-in fittings
      - Barbed fittings
        - Quick connector CK
        - Barbed fitting CN
        - Barbed hose fitting C-P N-P
        - Fitting NPCK

**QS+**

7842 **Quick connector**

Shipping date UVP/RRP 81403 → Deliver!

Pneumatic connection, port 1	Female thread G1/8
Pneumatic connection, port 2	For tubing outside diameter of 8 mm For barbed fitting inside diameter of 6 mm with nut
Ambient temperature	-10 ... 60 °C

**ACK-1/8-PK-6**

Type	Part no.	Designation	PU
> ACK-1/4-PK-6	3712	Quick connector	10
> ACK-1/8-PK-3	5664	Quick connector	10
> ACK-1/8-PK-4	3714	Quick connector	10
> ACK-1/8-PK-6	7842	Quick connector	10

**New Thai and Vietnamese**  
**Removed Russian, Latvian, Lithuanian**

# All accessories and recommended accessories like online catalog

The image shows a screenshot of the Festo online catalog interface. On the left, there are two filter panels. The top panel is titled 'Find the perfect accessories to complete your product assembly' and has a 'Filter by' section with two radio buttons: 'All Accessories' and 'Only recommended Accessories'. The 'Only recommended Accessories' option is selected and highlighted with a red box. Below this, there are several category dropdowns: 'Mounting accessories', 'Function fittings', 'Fittings', and 'Proximity sensors'. The bottom panel is also titled 'Find the perfect accessories to complete your product assembly' and has 'All Accessories' selected. Its dropdowns include 'Mounting accessories', 'Cylinder sensors for direct mounting', 'Function fittings', 'Other connectors', 'Barbed fittings', 'Quick connectors', and 'Push-in fittings'. A yellow box highlights these dropdowns. On the right, a product list is shown for 'DLGF-KF-25-150-PPSA'. A red box highlights the 'Recommended Accessories' section of the list. A blue arrow labeled 'Recommended accessories' points from the top filter panel to this section. Another blue arrow labeled 'All accessories' points from the bottom filter panel to the 'Function fittings' section of the product list, which is highlighted with a yellow box. The product list includes columns for part numbers, descriptions, and quantities.

Part Number	Description	Quantity
5072371	Linear actuator	
<b>Recommended Accessories</b>		
8069000	Cable holder	
8069000	Profile mounting	
8069000	Shock absorber ...	
8069002	Pneumatic choc...	
193144	One-way flow c...	
186096	Push-in fitting	
186107	Push-in fitting	
186117	Push-in L-fitting	
8059123	Proximity sensor	
8059124	Proximity sensor	
8059120	Proximity sensor	
8059121	Proximity sensor	
574339	Proximity sensor	
574338	Proximity sensor	
574334	Proximity sensor	
574335	Proximity sensor	
8068726	One-way flow c...	
<ul style="list-style-type: none"> <li>&gt; Function fittings</li> <li>&gt; Push-in fittings</li> <li>&gt; Quick connectors</li> <li>&gt; Other connectors</li> <li>&gt; Barbed fittings</li> <li>&gt; Mounting accessories</li> <li>&gt; Cylinder sensors for direct mounting</li> </ul>		

# Takeover of **AdditionalInformation.txt** and **Filter.txt** information to **Fluiddraw**



Highlight

8042559 - VUVG-BK10-M52-AT-F-1R8L-S Air solenoid valve Gewicht: 50 g (PK): 2.1.014 (ZA4) Zolltarifrnr.: 84812090 (DE) EUR 45,47

Close Product Finder Engineering New products History GTIN: 4052568286873 PL CE Kennzeichen: Copper-free: not Copper-free Kernprogramm: NO


**Products**

4 products selected

VUVG-BK10-M52-AT-F-1R8L-S	8042559	Air solenoid valve	50 g	84812090 (DE)
VUVG-BK10-T32C-AT-F-1H2L-S	8042554	Air solenoid valve	55 g	84812090 (DE)
VUVG-BK10-T32C-AT-F-1R8L-S	8042558	Air solenoid valve	55 g	84812090 (DE)
VUVG-BK14-B52-T-F-1H2L-S	8042572	Air solenoid valve	85 g	84812090 (DE)

Fluiddraw Copy CAD Compare products Show Online


Type	Part no.	Designation	PU	Gewicht	PG (PK)	Zolltarifrnr.:	EUR	PL	GTIN:	CE Kennzeichen:	Copper-free:	Kernp
> VUVG	564212	Air solenoid valve	1		2.1.011 (ZA4)	84812090 (DE)		Konfi...		nach EU-EMV...	not Copper-free	
> VUVG-BK10-B52-T-F-1H2L-S	8042556	Air solenoid valve	1	57 g	2.1.014 (ZA4)							
> VUVG-BK10-B52-T-F-1R8L-S	8042560	Air solenoid valve	1	50 g	2.1.014 (ZA4)							
> VUVG-BK10-M52-AT-F-1H2L-S	8042555	Air solenoid valve	1	45 g	2.1.014 (ZA4)							
> VUVG-BK10-M52-AT-F-1R8L-S	8042559	Air solenoid valve	1	50 g	2.1.014 (ZA4)							
> VUVG-BK10-T32C-AT-F-1H2L-S	8042554	Air solenoid valve	1	55 g	2.1.014 (ZA4)							
> VUVG-BK10-T32C-AT-F-1R8L-S	8042558	Air solenoid valve	1	55 g	2.1.014 (ZA4)							
> VUVG-BK14-B52-T-F-1H2L-S	8042572	Air solenoid valve	1	85 g	2.1.014 (ZA4)							
> VUVG-BK14-B52-T-F-1R8L-S	8042576	Air solenoid valve	1	85 g	2.1.014 (ZA4)							

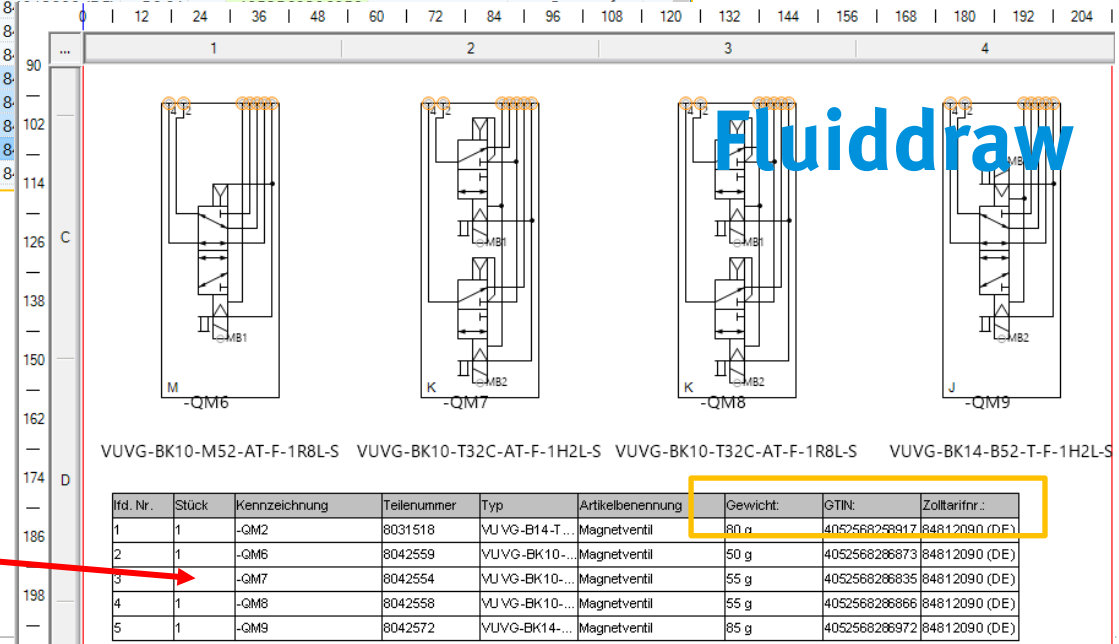

Insert Products from List

Menge	Teilenummer	Proc	Ker	Typ	Verpackung	Artikl	Meng	Beleg	Gewicht:	Zolltarifrnr.:	GTIN:	CE Kennzeichen:	Kernprogramm:	LABS haltige Stoffe enthalten	Auswahl
1	8042559			VUVG-BK10-M52-AT-F-...	1	Ma...	STK	VUV...	50 g	84812090 (DE)	4052568286873		NO	L	<input checked="" type="checkbox"/>
1	8042554			VUVG-BK10-T32C-AT-F-...	1	Ma...	STK	VUV...	55 g	84812090 (DE)	4052568286835		NO	L	<input checked="" type="checkbox"/>
1	8042558			VUVG-BK10-T32C-AT-F-...	1	Ma...	STK	VUV...	55 g	84812090 (DE)	4052568286866		NO	L	<input checked="" type="checkbox"/>
1	8042572			VUVG-BK14-B52-T-F-1...	1	Ma...	STK	VUV...	85 g	84812090 (DE)	4052568286972		NO	L	<input checked="" type="checkbox"/>

OK Cancel

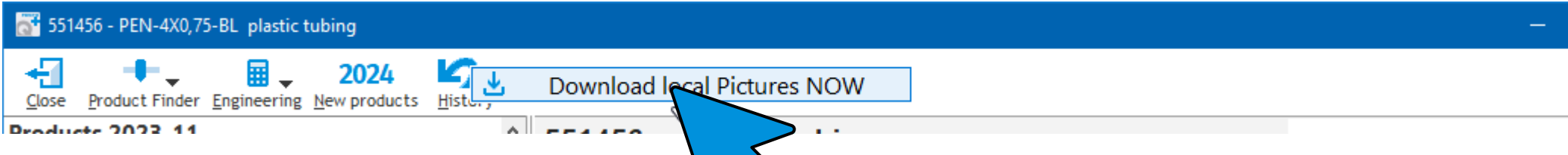

Small product thumbnail as **photo** (no black and white line drawing like before) Click this button to see

551456 - PEN-4X0,75-BL plastic tubing

2023-11

551456 plastic tubing  
PEN-4X0,75-BL  
Shipping date \$UVP/RRP 81403 → Deliver!

PEN-4X0,75-BL

Type	Part no.	Designation	PU
→	PEN-4X0,75-BL	551456 plastic tubing	50
→	PEN-4X0,75-BL-500	551444 plastic tubing	500
→	PEN-4X0,75-GE	551480 plastic tubing	50
→	PEN-4X0,75-GN	551468 plastic tubing	50
→	PEN-4X0,75-NT	543246 plastic tubing	50
→	PEN-4X0,75-RT	551474 plastic tubing	50
→	PEN-4X0,75-SI	551462 plastic tubing	50
→	PEN-4X0,75-SI-500	551450 plastic tubing	500
→	PEN-4X0,75-SW	543240 plastic tubing	50
→	PEN-4X0,75-SW-500	551438 plastic tubing	500
→	PEN-6X1-BL	551457 plastic tubing	50
→	PEN-6X1-BL-500	551445 plastic tubing	500
→	PEN-6X1-GE	551481 plastic tubing	50
→	PEN-6X1-GN	551469 plastic tubing	50
→	PEN-6X1-NT	543247 plastic tubing	50
→	PEN-6X1-RT	551475 plastic tubing	50
→	PEN-6X1-SI	551463 plastic tubing	50
→	PEN-6X1-SI-500	551451 plastic tubing	500
→	PEN-6X1-SW	543241 plastic tubing	50
→	PEN-6X1-SW-500	551439 plastic tubing	500
→	PEN-8X1,25-BL	551458 plastic tubing	50
→	PEN-8X1,25-BL-400	551446 plastic tubing	400
→	PEN-8X1,25-GE	551482 plastic tubing	50
→	PEN-8X1,25-GN	551470 plastic tubing	50
→	PEN-8X1,25-NT	543248 plastic tubing	50

551456 - PEN-4X0,75-BL Plastic tubing


2024-01

551456 Plastic tubing  
PEN-4X0,75-BL  
Shipping date \$UVP/RRP 81403 → Deliver!

PEN-4X0,75-BL

Type	Part no.	Designation	PU
→	PEN-4X0,75-BL	551456 Plastic tubing	50
→	PEN-4X0,75-BL-500	551444 Plastic tubing	500
→	PEN-4X0,75-GE	551480 Plastic tubing	50
→	PEN-4X0,75-GN	551468 Plastic tubing	50
→	PEN-4X0,75-NT	543246 Plastic tubing	50
→	PEN-4X0,75-RT	551474 Plastic tubing	50
→	PEN-4X0,75-SI	551462 Plastic tubing	50
→	PEN-4X0,75-SI-500	551450 Plastic tubing	500
→	PEN-4X0,75-SW	543240 Plastic tubing	50
→	PEN-4X0,75-SW-500	551438 Plastic tubing	500
→	PEN-6X1-BL	551457 Plastic tubing	50
→	PEN-6X1-BL-500	551445 Plastic tubing	500
→	PEN-6X1-GE	551481 Plastic tubing	50
→	PEN-6X1-GN	551469 Plastic tubing	50
→	PEN-6X1-NT	543247 Plastic tubing	50
→	PEN-6X1-RT	551475 Plastic tubing	50
→	PEN-6X1-SI	551463 Plastic tubing	50
→	PEN-6X1-SI-500	551451 Plastic tubing	500
→	PEN-6X1-SW	543241 Plastic tubing	50
→	PEN-6X1-SW-500	551439 Plastic tubing	500
→	PEN-8X1,25-BL	551458 Plastic tubing	50
→	PEN-8X1,25-BL-400	551446 Plastic tubing	400
→	PEN-8X1,25-GE	551482 Plastic tubing	50
→	PEN-8X1,25-GN	551470 Plastic tubing	50
→	PEN-8X1,25-NT	543248 Plastic tubing	50



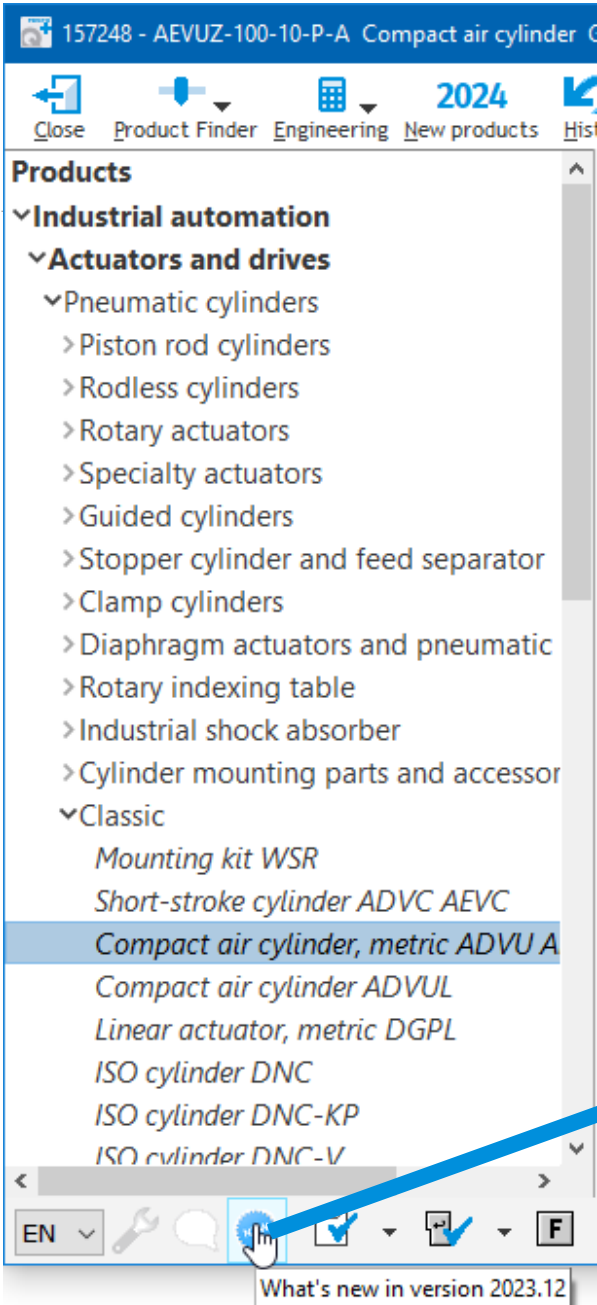

Button **What is new in version xxx**





## bugs fixes and minor improvements

### Short description

Fix column width when **copy parts list to Online-Outlook** in Browser

When moving mouse on tiny product thumbnail, product picture turned white

Removed unit conversion tool from internal SPIMS+ menu (tool no more available)

Fixed an issue with phased-out MS4- and MS6- products which are part of KMAT now