


Dummy plug
NEAC-M-S-BD-R3SCPP
Part number: 8090740

FESTO

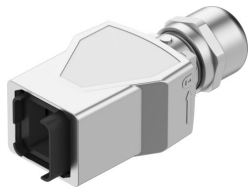

Data sheet

Feature	Value
Width	34 mm
Height	22.4 mm
Length	69.2 mm
Product weight	75.4 g
Size of pack	1
Electrical connection 1, connector system	For RJ45 and SC-RJ
Electrical connection 1, type of mounting	Push-pull
Degree of protection	IP65 IP67
Note on degree of protection	In assembled state
Ambient temperature	-40 °C...70 °C
Storage temperature	-40 °C...70 °C
LABS (PWIS) conformity	VDMA24364-A1-L
Note on materials	RoHS-compliant
Corrosion resistance class CRC	1 - Low corrosion stress
Housing colour	Silver
Material housing	Die-cast zinc, nickel-plated
Material seals	NBR
Fire test	UL94 V-0