


# Check valve VBNF-CBA-Q6-Q6

Part number: 8193270

**FESTO**

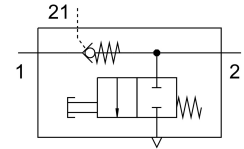

## Data sheet

Feature	Value
Valve function	Non-return function
Pneumatic connection, port 1	QS-6
Pneumatic connection, port 2	QS-6
Pilot air port 21	QS-6
Type of actuation	Manual
Standard nominal flow rate	260 l/min
Operating pressure	1 MPa 10 bar
Pilot pressure	0.2 MPa...1 MPa 2 bar...10 bar 29 psi...145 psi
Ambient temperature	-10 °C...60 °C
Material housing	PBT
Housing colour	grey
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Mounting position	optional
Type act., cont. n.-r. func.	Pneumatic
Manual exhaust function	Non-detenting
Operating pressure complete temperature range	0.2 bar...10 bar
Standard flow rate 1->2 (6-0)	500 l/min
Standard nominal flow rate 1->2 (6-5)	260 l/min
Switching time off	9 ms
Switching time on	6 ms
Explosion protection	Zone 2 (ATEX) Zone 22 (ATEX)
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C...70 °C
Media temperature	-10 °C...60 °C
Pilot medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Product weight	23.3 g

<b>Feature</b>	<b>Value</b>
Material covering	ES-BE
Note on materials	RoHS-compliant
Material cover	PBT
Material seals	NBR
Material release ring	POM