


# Axial kit EAMM-A-N48-100A-G2

Part number: 8197464

FESTO

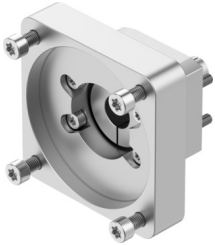

## Data sheet

Feature	Value
Nominal length	59 mm
Mounting position	optional
Max. rotational speed	6000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	39 kgmm <sup>2</sup>
Transmittable torque	17 Nm
Product weight	851 g
Interface code, actuator	N48
Interface code, motor in	100A
Note on materials	RoHS-compliant