


Axial kit EAMM-A-X48-87A

Part number: 8210061

FESTO

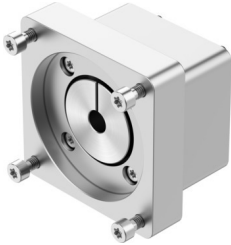

Data sheet

| Feature | Value |
|--------------------------|--------------------|
| Mounting position | optional |
| Max. rotational speed | 6000 rpm |
| LABS (PWIS) conformity | VDMA24364 zone III |
| Storage temperature | -25 °C...60 °C |
| Relative air humidity | 0 - 95% |
| Degree of protection | IP40 |
| Ambient temperature | -10 °C...60 °C |
| Transmittable torque | 17 Nm |
| Product weight | 808 g |
| Interface code, actuator | X48 |
| Interface code, motor in | 87A |
| Note on materials | RoHS-compliant |