


# Axial kit EAMM-A-C42-8-89CA-S5

Part number: 8230179

FESTO

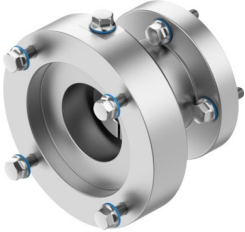

## Data sheet

Feature	Value
Nominal length	60.5 mm
Mounting position	optional
Gear unit ratio	1:1
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 100%
Degree of protection	IP69K
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	5.87 kgmm <sup>2</sup>
Transmittable torque	6.5 Nm
Product weight	1140 g
Interface code, actuator	C42-8
Interface code, motor in	89CA
Note on materials	RoHS-compliant