


Axial kit EAMM-A-C50-10-80CA-S5

Part number: 8230181

FESTO

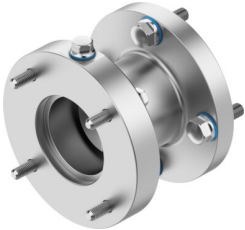

Data sheet

| Feature | Value |
|--------------------------|------------------------|
| Nominal length | 58 mm |
| Mounting position | optional |
| Gear unit ratio | 1:1 |
| Max. rotational speed | 8000 rpm |
| LABS (PWIS) conformity | VDMA24364 zone III |
| Storage temperature | -25 °C...60 °C |
| Relative air humidity | 0 - 100% |
| Degree of protection | IP69K |
| Ambient temperature | -10 °C...60 °C |
| Mass moment of inertia | 5.87 kgmm ² |
| Transmittable torque | 12.5 Nm |
| Product weight | 930 g |
| Interface code, actuator | C50-10 |
| Interface code, motor in | 80CA |
| Note on materials | RoHS-compliant |