


# Cover plate VABB-P19-16-T

Part number: 8154656

FESTO

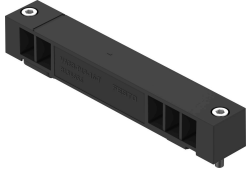

## Data sheet

Feature	Value
Size	16
Width dimension	16 mm
Sealing principle	Soft
Operating pressure	-0.1 MPa...0.7 MPa -1 bar...7 bar
Suitability for vacuum	yes
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-20 °C...70 °C
Temperature of medium	5 °C...50 °C
Degree of protection	IP65
Ambient temperature	5 °C...50 °C
Nominal tightening torque	0.75 Nm
Product weight	14.9 g
Electrical connection	Plug-in
Type of mounting	With through-hole and screw
Note on materials	RoHS-compliant
Seals material	EPDM
Housing material	PA66-GF30