


Gripper jaw mounting EHAA-G1-E20-40-GGA1-AP

Part number: 8191126

FESTO

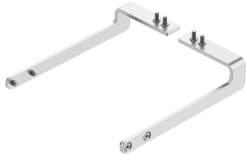

Data sheet

Feature	Value
Size	40
Mounting position	Any
Structural design	vertical gripper mounting
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-20 °C...70 °C
Relative air humidity	0 - 100 %
Ambient temperature	0 °C...40 °C
Product weight	95 g
Note on materials	RoHS-compliant
Material of screws	High-alloy stainless steel
Bracket material	High-alloy stainless steel
Material of centering elements	High-alloy steel