


Axial kit EAMM-A-L38-60R-G2

Part number: 8197451

FESTO

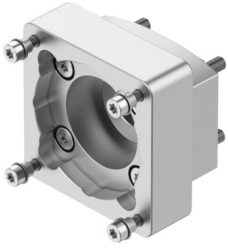

Data sheet

| Feature | Value |
|--------------------------|-----------------------|
| Nominal length | 36 mm...36 mm |
| Mounting position | Any |
| Max. rotational speed | 8000 rpm...8000 rpm |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Storage temperature | -25 °C...-25 °C |
| Relative air humidity | 0 - 95 % |
| Degree of protection | IP40 |
| Ambient temperature | -10 °C...-10 °C |
| Mass moment of inertia | 3.2 kgmm ² |
| Transferable torque | 4.4 Nm |
| Product weight | 254 g...254 g |
| Interface code, actuator | L38 |
| Interface code, motor in | 60R |
| Note on materials | RoHS-compliant |