


Axial kit EAMM-A-N38-60H-G2

Part number: 8197463

FESTO

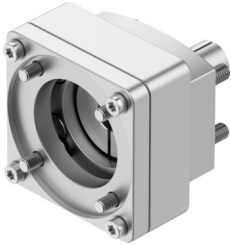

Data sheet

Feature	Value
Nominal length	41 mm...41 mm
Mounting position	Any
Max. rotational speed	8000 rpm...8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...-25 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C...-10 °C
Mass moment of inertia	14.5 kgmm ²
Transferable torque	16 Nm
Product weight	374 g...374 g
Interface code, actuator	N38
Interface code, motor in	60H
Note on materials	RoHS-compliant