


# Axial kit EAMM-A-N48-80G-G2

Part number: 8197470

FESTO

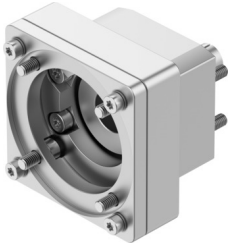

## Data sheet

| Feature                  | Value                |
|--------------------------|----------------------|
| Nominal length           | 59 mm                |
| Mounting position        | Any                  |
| Max. rotational speed    | 6000 rpm             |
| LABS (PWIS) conformity   | VDMA24364-B2-L       |
| Storage temperature      | -25 °C...60 °C       |
| Relative air humidity    | 0 - 95 %             |
| Degree of protection     | IP40                 |
| Ambient temperature      | -10 °C...60 °C       |
| Mass moment of inertia   | 39 kgmm <sup>2</sup> |
| Transferable torque      | 21 Nm                |
| Product weight           | 689 g                |
| Interface code, actuator | N48                  |
| Interface code, motor in | 80G                  |
| Note on materials        | RoHS-compliant       |