


Axial kit EAMM-A-S48-60H-G3

Part number: 8197482

FESTO

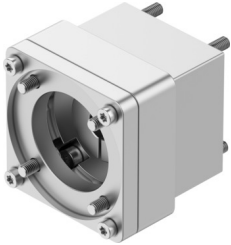

Data sheet

Feature	Value
Nominal length	55.5 mm...55.5 mm
Mounting position	Any
Max. rotational speed	8000 rpm...8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...-25 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C...-10 °C
Mass moment of inertia	5.87 kgmm ²
Transferable torque	12.5 Nm
Product weight	340 g...340 g
Interface code, actuator	S48
Interface code, motor in	60H
Note on materials	RoHS-compliant