


# Axial kit EAMM-A-S62-100A-G3

Part number: 8197486

FESTO

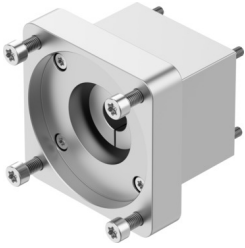

## Data sheet

| Feature                  | Value                  |
|--------------------------|------------------------|
| Nominal length           | 80 mm...80 mm          |
| Mounting position        | Any                    |
| Max. rotational speed    | 6000 rpm...6000 rpm    |
| LABS (PWIS) conformity   | VDMA24364-B2-L         |
| Storage temperature      | -25 °C...-25 °C        |
| Relative air humidity    | 0 - 95 %               |
| Degree of protection     | IP40                   |
| Ambient temperature      | -10 °C...-10 °C        |
| Mass moment of inertia   | 34.8 kgmm <sup>2</sup> |
| Transferable torque      | 21 Nm                  |
| Product weight           | 1250 g...1250 g        |
| Interface code, actuator | S62                    |
| Interface code, motor in | 100A                   |
| Note on materials        | RoHS-compliant         |