


# Axial kit EAMM-A-D60-100A-S1-G2

Part number: 8197490

FESTO

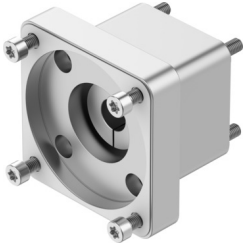

## Data sheet

Feature	Value
Nominal length	78.4 mm...78.4 mm
Mounting position	Any
Max. rotational speed	6000 rpm...6000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...-25 °C
Relative air humidity	0 - 95 %
Degree of protection	IP65
Ambient temperature	-10 °C...-10 °C
Mass moment of inertia	34.8 kgmm <sup>2</sup>
Transferable torque	21 Nm
Product weight	1310 g...1310 g
Interface code, actuator	D60
Interface code, motor in	100A
Note on materials	RoHS-compliant