


Axial kit EAMM-A-D32-60P-S1-G2

Part number: 8197495

FESTO

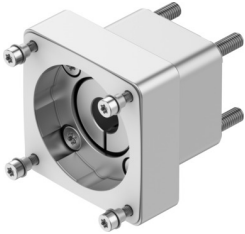

Data sheet

| Feature | Value |
|--------------------------|------------------------|
| Nominal length | 51 mm...51 mm |
| Mounting position | Any |
| Max. rotational speed | 8000 rpm...8000 rpm |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Storage temperature | -25 °C...-25 °C |
| Relative air humidity | 0 - 95 % |
| Degree of protection | IP65 |
| Ambient temperature | -10 °C...-10 °C |
| Mass moment of inertia | 5.87 kgmm ² |
| Transferable torque | 6.5 Nm |
| Product weight | 380 g...380 g |
| Interface code, actuator | D32 |
| Interface code, motor in | 60P 60PA |
| Note on materials | RoHS-compliant |