


# Pressure amplifier PBPA-63-16-A

Part number: 8210531

FESTO

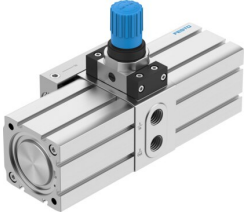

## Data sheet

Feature	Value
Piston diameter	63 mm
Mounting position	Any
Structural design	Twin-piston pressure intensifier
Pressure gauge	G1/8 prepared
Output pressure 2	0.4 MPa...1.6 MPa 58 psi...232 psi
Outlet pressure 2	4 bar...16 bar
Operating pressure	0.2 MPa...1 MPa 2 bar...10 bar 29 psi...145 psi
Inlet pressure 1	2 bar...10 bar
Inlet pressure 1 MPa	0.2 MPa...1 MPa
Inlet pressure 1 psi	29 psi...145 psi
Operating medium	Compressed air as per ISO 8573-1:2010 [7:3:4]
Information on operating and pilot media	Operation with oil lubrication not possible
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	5 °C...60 °C
Ambient temperature	5 °C...60 °C
Product weight	3150 g
Type of mounting	With internal thread
Pneumatic connection 1	G3/8
Pneumatic connection 2	G3/8
Pneumatic connection 3	G1/4
Note on materials	RoHS-compliant