


# Suction cup with connector OGVM-80-G-N-G38F

Part number: 8211023

FESTO

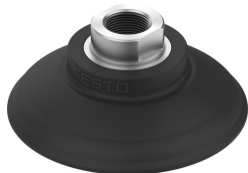

## Data sheet

Feature	Value
Suction cup height compensation	12.8 mm
Min. workpiece radius	45 mm
Nominal width	7 mm
Suction cup diameter	80 mm
Suction cup volume	48 cm <sup>3</sup>
Connection position	Top
Mounting position	Any
Suction cup shape	Round bell-shaped
Operating pressure	-95 kPa...0 kPa -0.95 bar...0 bar -13.775 psi...0 psi
Nominal operating pressure	-60 kPa -0.6 bar -8.7 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-A1/A2-L
Ambient temperature	-20 °C...80 °C
Holding force at nominal operating pressure	220 N
Lateral force at nominal operating pressure	241 N
Product weight	45 g
Type of mounting	Via vacuum connection
Vacuum connection	Internal thread G3/8
Color	Black
Shore hardness	60 +/- 5
Material of screwed plug	Wrought aluminum alloy
Note on materials	RoHS-compliant
Suction cup material	NBR