


Inline filter **OAFA-C-Q4-E-F** Part number: 8212637

FESTO

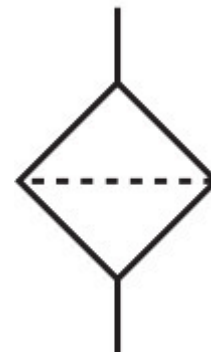

Data sheet

Feature	Value
Nominal width	4 mm
Application note	The housing should not be cleaned with polar solvents (such as alcohol).
Mounting position	Any
Grade of filtration	10 µm
Operating pressure	-0.1 MPa...1 MPa -1 bar...10 bar -14.5 psi...145 psi
Operating medium	Air
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Suitability for the production of Li-ion batteries	Suitable for battery production in accordance with Festo's internal definition in degree of severity F1A with restrictions regarding the use of Cu/Zn/Ni
Ambient temperature	0 °C...60 °C
Product weight	5.4 g
Type of mounting	Line installation
Pneumatic connection	For pneumatic tubing outside diameter 4 mm
Note on materials	RoHS-compliant
Seals material	HNBR
Compressed air filter material	PE
Housing material	PA